

POWER EXIT WIRE BAY 400MM

POWER BAY 800MM

POWER BAY 600MM

POWER BAY 800MM

INPUT BAY 1000MM

2x POWER ENTRY WIRE BAY 400MM


INPUT BAY 1000MM

POWER BAY 800MM

POWER BAY 600MM



POWER BAY 800MM

POWER EXIT WIRE BAY 400MM

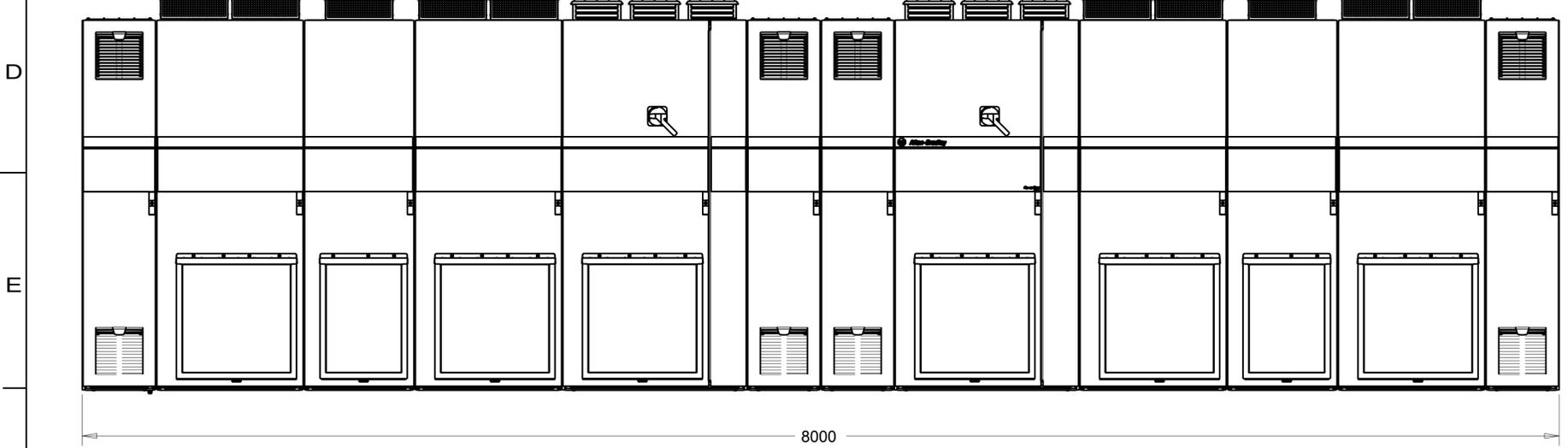

IP21/UL TYPE 1


IP54/UL TYPE 12

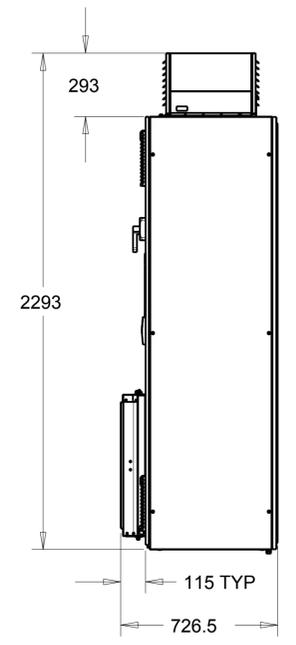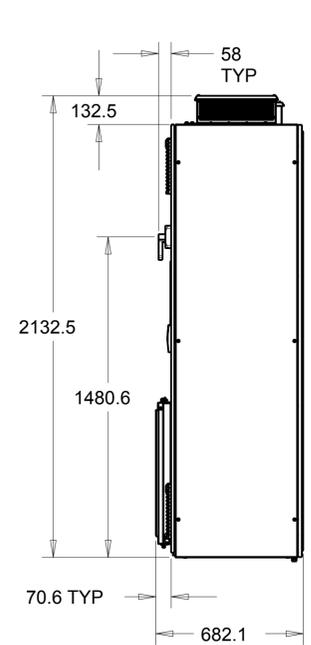

NOTES:

- ENCLOSURE SYSTEM IS 2000MM TALL 600MM DEEP
- PLEASE CHECK ROCKWELLAUTOMATION.LITERATURE.COM FOR ADDITIONAL INFORMATION ON THE POWERFLEX 755T DRIVES.
- DRIVE SIZE SHOWN:

INPUT VOLTAGE	NORMAL DUTY RATING
400	2200 kW
480	3600 HP
600	3100 HP
690	2750 kW

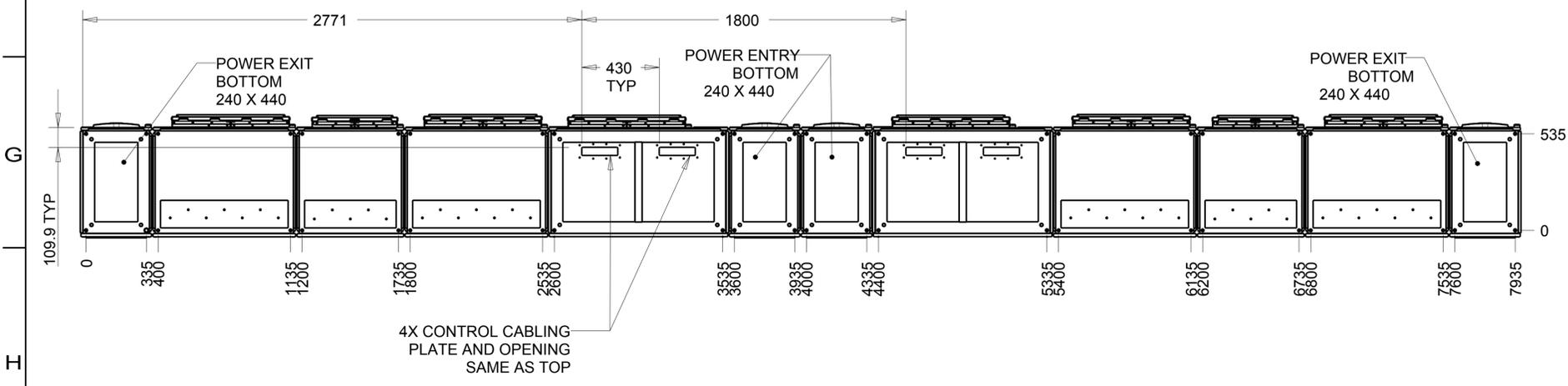


DIMENSIONS IN MM
UNLESS OTHERWISE SPECIFIED
DIMENSIONS & TOLERANCING IN ACCORDANCE WITH ASME Y14.5-2009
ALL UNTOLERANCED DIMENSIONS ARE BASIC AND CONTROLLED BY CAD MODEL AND CONTROLLED SIMULTANEOUSLY.

Rockwell Automation

PF755TR AFE DRIVES FRAME13
INLINE INSTALLATION SPECIFICATION

Drawn by: MLACHAW Date: JAN-17-2018

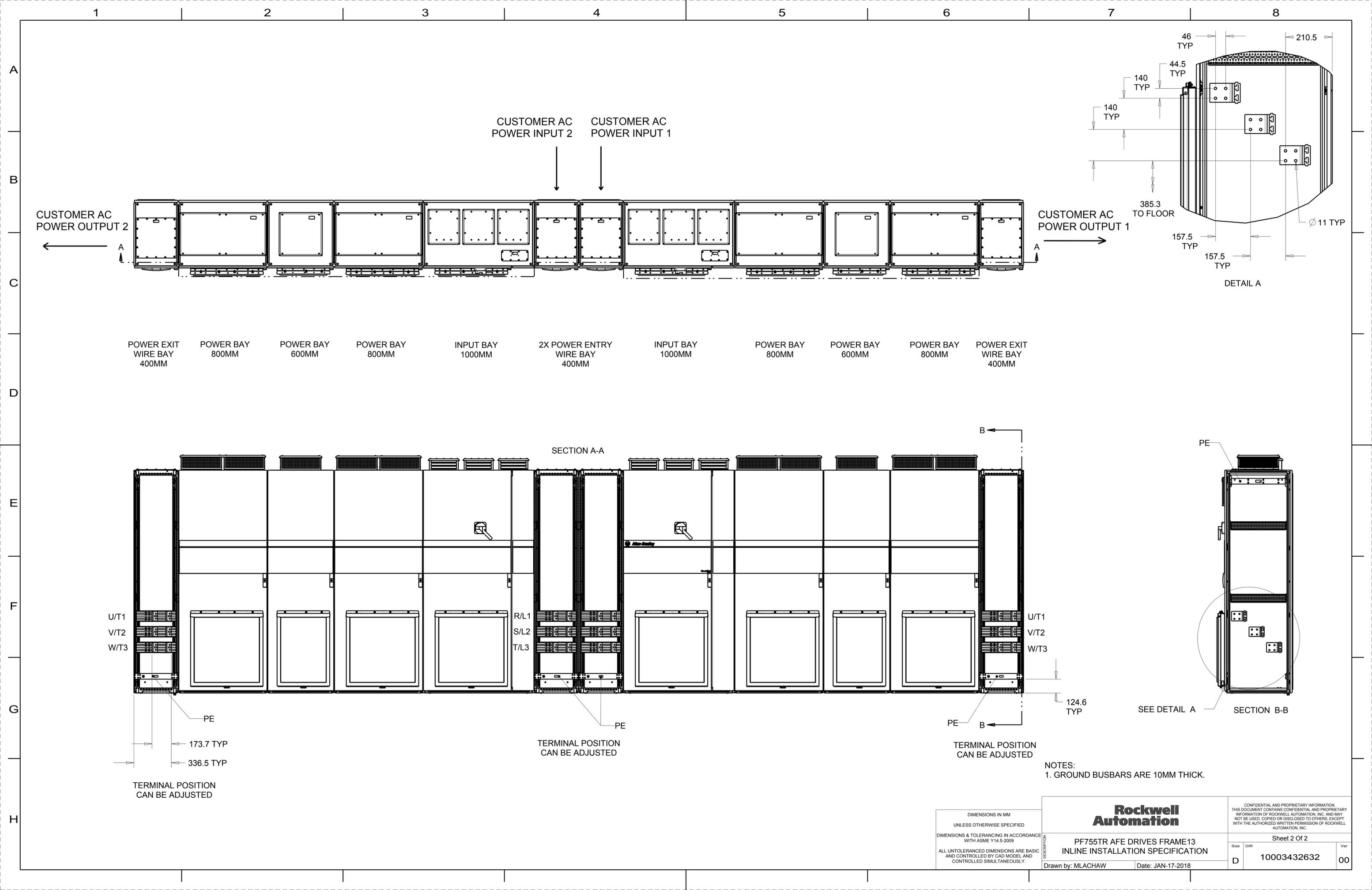

DIMENSIONS IN MM
UNLESS OTHERWISE SPECIFIED
DIMENSIONS & TOLERANCING IN ACCORDANCE WITH ASME Y14.5-2009
ALL UNTOLERANCED DIMENSIONS ARE BASIC AND CONTROLLED BY CAD MODEL AND CONTROLLED SIMULTANEOUSLY.

Rockwell Automation

PF755TR AFE DRIVES FRAME 13
INLINE INSTALLATION SPECIFICATION

Drawn by: MLACHAW Date: JAN-17-2018

CONFIDENTIAL AND PROPRIETARY INFORMATION THIS DOCUMENT CONTAINS CONFIDENTIAL AND PROPRIETARY INFORMATION OF ROCKWELL AUTOMATION, INC. AND MAY NOT BE USED, COPIED OR DISCLOSED TO OTHERS, EXCEPT WITH THE AUTHORIZED WRITTEN PERMISSION OF ROCKWELL AUTOMATION, INC.		
Sheet 2 Of 2		
Size	DIR	Ver
D	10003432632	00