

Screw Connection Terminal Blocks



Internal Components Blocks (Diode, Resistor, Surge Suppressor), Continued

1492-JD3RC001*

1492-JD3SS

Dimensions are not intended to be used for manufacturing purposes.

Note: Height dimension is measured from top of rail to top of terminal block.

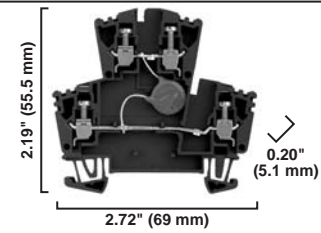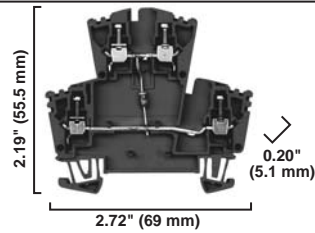

Specifications

Two Level terminal block with a 249 ohm resistor between the 2 levels

Two Level terminal block with an MOV between the 2 levels.

Certifications		CSA	IEC		CSA	IEC
Voltage Rating	600V AC/DC	300V AC/DC	400V AC/DC	600V AC/DC	115V AC/DC	
Resistor Type	Precision Wire Wound					
Resistor Value	249 Ω, 1/2 W					
Current through Busbar	20 A	10 A	—	20 A	10 A	24 A
Wire Range (Rated Cross Section)	#22...12 AWG	#26...12 AWG	2.5 mm ²	#22...12 AWG	#26...12 AWG	2.5 mm ²
Wire Strip Length	0.39 in. (10 mm)			0.39 in. (10 mm)		
Recommended Tightening Torque	4.5...7.1 lb•in. (0.5...0.8 N•m)			4.5...7.1 lb•in. (0.5...0.8 N•m)		
Density	59 pcs/ft (196 pcs/m)			59 pcs/ft (196 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)			-58...+248 °F (-50...+120 °C)		

Terminal Blocks

	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Color: Grey	1492-JD3RC001	1	1492-JD3SS	1

Accessories

	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Mounting Rails:				
1 m Symmetrical DIN (Steel)	199-DR1	10	199-DR1	10
1 m Symmetrical DIN (Aluminum)	1492-DR5	10	1492-DR5	10
1 m Hi-Rise Sym. DIN (Aluminum)	1492-DR6	2	1492-DR6	2
1 m Angled Hi-Rise Sym. DIN (Steel)	1492-DR7	2	1492-DR7	2
End Barrier	1492-EBJD3	20	1492-EBJD3	20
End Anchors:				
Screwless End Retainer	1492-ERL35	20	1492-ERL35	20
DIN Rail — Normal Duty	1492-EAJ35	100	1492-EAJ35	100
DIN Rail — Heavy Duty	1492-EAHJ35	50	1492-EAHJ35	50
Jumpers:				
Screw Center Jumper — 10-pole	1492-CJJ5-10	20	1492-CJJ5-10	20
Screw Center Jumper — 4-pole	1492-CJJ5-4	50	1492-CJJ5-4	50
Screw Center Jumper — 3-pole	1492-CJJ5-3	50	1492-CJJ5-3	50
Screw Center Jumper — 2-pole	1492-CJJ5-2	50	1492-CJJ5-2	50
Insulated Side Jumper — 24-Pole	1492-SJ5A-24	50	1492-SJ5A-24	50
Insulated Side Jumper — 10-Pole	1492-SJ5A-10	50	1492-SJ5A-10	50
Screw Type Jumper Notching Tool	1492-T1	1	1492-T1	1
Other Accessories:				
Partition Plate	1492-PPJD3	20	1492-PPJD3	20
Group Marking Carrier	1492-GM35	25	1492-GM35	25
Marking Systems:				
Snap-in marker card	1492-M5X8 (144/card)	5	1492-M5X8 (144/card)	5
Snap-in marker card	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5

* See page 12-89 for component specifications.