



# Screw Connection Terminal Blocks

## Grounding Blocks, Continued

## 1492-JG6

## 1492-JG10

Dimensions are not intended to be used for manufacturing purposes.  
**Note:** Height dimension is measured from top of rail to top of terminal block.

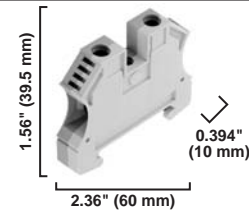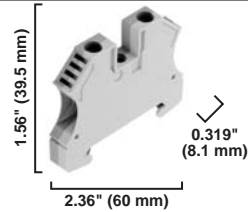

Specifications	Feed-Through Ground Block				Feed-Through Ground Block			
Certifications		CSA	IEC	ATEX		CSA	IEC	ATEX
Voltage Rating	—	—	—	—	—	—	—	—
Maximum Current	Grounding				Grounding			
Wire Range (Rated Cross Section)	#22...8 AWG	6 mm <sup>2</sup>	6 mm <sup>2</sup> (#20... 10 AWG)		#16...6 AWG	10 mm <sup>2</sup>	10 mm <sup>2</sup> (#16... 8 AWG)	
Wire Strip Length	0.47 in. (12 mm)				0.47 in. (12 mm)			
Recommended Tightening Torque	14.2 lb•in. (1.6 N•m)				20.4 lb•in. (2.3 N•m)			
Mounting Torque — Center Screw	4.4...8.9 lb•in. (0.5...1.0 N•m)				4.4...8.9 lb•in. (0.5...1.0 N•m)			
Density	37 pcs/ft (123 pcs/m)				30 pcs/ft (100 pcs/m)			
Housing Temperature Range	-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)			
Short-Circuit Current Rating	See page 12-43							
<b>Terminal Blocks</b>	<b>Cat. No.</b>			<b>Pkg Qty.</b>	<b>Cat. No.</b>			<b>Pkg Qty.</b>
Color: Green/Yellow	<b>1492-JG6</b>			50	<b>1492-JG10</b>			50
<b>Accessories</b>	<b>Cat. No.</b>			<b>Pkg Qty.</b>	<b>Cat. No.</b>			<b>Pkg Qty.</b>
Mounting Rails:								
1 m Symmetrical DIN (Steel)	<b>199-DR1</b>			10	<b>199-DR1</b>			10
1 m Symmetrical DIN (Aluminum)	<b>1492-DR5</b>			10	<b>1492-DR5</b>			10
1 m Hi-Rise Sym. DIN (Aluminum)	<b>1492-DR6</b>			2	<b>1492-DR6</b>			2
1 m Angled Hi-Rise Sym. DIN (Steel)	<b>1492-DR7</b>			2	<b>1492-DR7</b>			2
End Anchors and End Retainers:								
Screwless End Retainer	<b>1492-ERL35</b>			20	<b>1492-ERL35</b>			20
DIN Rail — Normal Duty	<b>1492-EAJ35</b>			100	<b>1492-EAJ35</b>			100
DIN Rail — Heavy Duty	<b>1492-EAHJ35</b>			50	<b>1492-EAHJ35</b>			50
Other Accessories:								
Group Marking Carrier	<b>1492-GM35</b>			25	<b>1492-GM35</b>			25
Marking Systems:								
Snap-in marker cards	<b>1492-MR8X12</b> (84/card)			5	<b>1492-M7X12</b> (108/card)			5
Snap-in marker cards	<b>1492-M8X5</b> (160/card)			5	<b>1492-M8X5</b> (160/card)			5