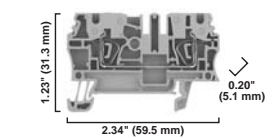
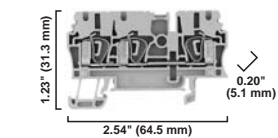
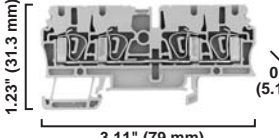


Spring-Clamp Connection Terminal Blocks

Standard Feed-Through Blocks, Continued

	1492-L3				1492-L3T				1492-L3Q			
Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block.												
Specifications	Feed-through Terminal Block				Feed-through Terminal Block with 2 points on one side				Feed-through Terminal Block with 2 points on each side			
Certifications		CSA	IEC	ATEX		CSA	IEC	ATEX		CSA	IEC	ATEX
Voltage Rating	600V AC/DC		800V AC/DC	550V AC/DC	600V AC/DC		800V AC/DC	550V AC/DC	600V AC/DC		800V AC/DC	550V AC/DC
Maximum Current	25 A	27 A	24 A	21 A	25 A	27 A	24 A	21 A	25 A	27 A	24 A	21 A
Wire Range (Rated Cross Section)	#30...1 2 AWG	#26... 12 AWG	2.5 mm ²	2.5 mm ² (20...12 AWG)	#30...1 2 AWG	#26... 12 AWG	2.5 mm ²	2.5 mm ² (20...12 AWG)	#30...1 2 AWG	#26... 12 AWG	2.5 mm ²	2.5 mm ² (20...12 AWG)
Wire Strip Length	0.39 in. (10 mm)				0.39 in. (10 mm)				0.39 in. (10 mm)			
Density	59 pcs/ft (196 pcs/m)				59 pcs/ft (196 pcs/m)				59 pcs/ft (196 pcs/m)			
Housing Temperature Range	-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)			
Short-Circuit Current Rating (SCCR)	See page 12-71											
Terminal Blocks	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Color	Grey	1492-L3	100	1492-L3T	100	1492-L3Q	100	1492-L3Q	100	1492-L3Q	100	1492-L3Q
	Red	1492-L3-RE	100	1492-L3T-RE	100	1492-L3Q-RE	100	1492-L3Q-RE	100	1492-L3Q-RE	100	1492-L3Q-RE
	Blue	1492-L3-B	100	1492-L3T-B	100	1492-L3Q-B	100	1492-L3Q-B	100	1492-L3Q-B	100	1492-L3Q-B
	Black	1492-L3-BL	100	1492-L3T-BL	100	1492-L3Q-BL	100	1492-L3Q-BL	100	1492-L3Q-BL	100	1492-L3Q-BL
	Green	1492-L3-G	100	1492-L3T-G	100	1492-L3Q-G	100	1492-L3Q-G	100	1492-L3Q-G	100	1492-L3Q-G
	Yellow	1492-L3-Y	100	1492-L3T-Y	100	1492-L3Q-Y	100	1492-L3Q-Y	100	1492-L3Q-Y	100	1492-L3Q-Y
	Orange	1492-L3-OR	100	1492-L3T-OR	100	1492-L3Q-OR	100	1492-L3Q-OR	100	1492-L3Q-OR	100	1492-L3Q-OR
	Brown	1492-L3-BR	100	1492-L3T-BR	100	1492-L3Q-BR	100	1492-L3Q-BR	100	1492-L3Q-BR	100	1492-L3Q-BR
	White	1492-L3-W	100	1492-L3T-W	100	1492-L3Q-W	100	1492-L3Q-W	100	1492-L3Q-W	100	1492-L3Q-W
Accessories	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Mounting Rails												
1 m Symmetrical DIN (Steel)	199-DR1	10	199-DR1	10	199-DR1	10	199-DR1	10	199-DR1	10	199-DR1	10
1 m Symmetrical DIN (Aluminum)	1492-DR5	10	1492-DR5	10	1492-DR5	10	1492-DR5	10	1492-DR5	10	1492-DR5	10
1 m Hi-Rise Sym. DIN (Aluminum)	1492-DR6	2	1492-DR6	2	1492-DR6	2	1492-DR6	2	1492-DR6	2	1492-DR6	2
1 m Angled Hi-Rise Sym. DIN (Steel)	1492-DR7	2	1492-DR7	2	1492-DR7	2	1492-DR7	2	1492-DR7	2	1492-DR7	2
End Barriers												
Grey	1492-EBL3	50	1492-EBL3T	50	1492-EBL3Q	50	1492-EBL3Q	50	1492-EBL3Q	50	1492-EBL3Q	50
Blue	1492-EBL3-B	50	1492-EBL3T-B	50	1492-EBL3Q-B	50	1492-EBL3Q-B	50	1492-EBL3Q-B	50	1492-EBL3Q-B	50
Yellow	1492-EBL3-Y	50	1492-EBL3T-Y	50	1492-EBL3Q-Y	50	1492-EBL3Q-Y	50	1492-EBL3Q-Y	50	1492-EBL3Q-Y	50
End Anchors and Retainers												
Screwless End Retainer	1492-ERL35	20	1492-ERL35	20	1492-ERL35	20	1492-ERL35	20	1492-ERL35	20	1492-ERL35	20
DIN Rail — Normal Duty	1492-EAJ35	100	1492-EAJ35	100	1492-EAJ35	100	1492-EAJ35	100	1492-EAJ35	100	1492-EAJ35	100
DIN Rail — Heavy Duty	1492-EAHJ35	50	1492-EAHJ35	50	1492-EAHJ35	50	1492-EAHJ35	50	1492-EAHJ35	50	1492-EAHJ35	50
Jumpers												
Plug-in Center Jumper — 50-Pole	1492-CJK5-50	10	1492-CJK5-50	10	1492-CJK5-50	10	1492-CJK5-50	10	1492-CJK5-50	10	1492-CJK5-50	10
Plug-in Center Jumper — 10-Pole	1492-CJK5-10	20	1492-CJK5-10	20	1492-CJK5-10	20	1492-CJK5-10	20	1492-CJK5-10	20	1492-CJK5-10	20
Plug-in Center Jumper — 9-Pole	1492-CJK5-9	20	1492-CJK5-9	20	1492-CJK5-9	20	1492-CJK5-9	20	1492-CJK5-9	20	1492-CJK5-9	20
Plug-in Center Jumper — 8-Pole	1492-CJK5-8	20	1492-CJK5-8	20	1492-CJK5-8	20	1492-CJK5-8	20	1492-CJK5-8	20	1492-CJK5-8	20
Plug-in Center Jumper — 7-Pole	1492-CJK5-7	20	1492-CJK5-7	20	1492-CJK5-7	20	1492-CJK5-7	20	1492-CJK5-7	20	1492-CJK5-7	20
Plug-in Center Jumper — 6-Pole	1492-CJK5-6	20	1492-CJK5-6	20	1492-CJK5-6	20	1492-CJK5-6	20	1492-CJK5-6	20	1492-CJK5-6	20
Plug-in Center Jumper — 5-Pole	1492-CJK5-5	20	1492-CJK5-5	20	1492-CJK5-5	20	1492-CJK5-5	20	1492-CJK5-5	20	1492-CJK5-5	20
Plug-in Center Jumper — 4-Pole	1492-CJK5-4	60	1492-CJK5-4	60	1492-CJK5-4	60	1492-CJK5-4	60	1492-CJK5-4	60	1492-CJK5-4	60
Plug-in Center Jumper — 3-Pole	1492-CJK5-3	60	1492-CJK5-3	60	1492-CJK5-3	60	1492-CJK5-3	60	1492-CJK5-3	60	1492-CJK5-3	60
Plug-in Center Jumper — 2-Pole	1492-CJK5-2	60	1492-CJK5-2	60	1492-CJK5-2	60	1492-CJK5-2	60	1492-CJK5-2	60	1492-CJK5-2	60
Other Accessories												
Reducing Sleeves #30...#24 AWG (0.13...0.2 mm ²) White	1492-PSL3-2	100	1492-PSL3-2	100	1492-PSL3-2	100	1492-PSL3-2	100	1492-PSL3-2	100	1492-PSL3-2	100
Reducing Sleeves #22...#20 AWG (0.25...0.5 mm ²) Grey	1492-PSL3-5	100	1492-PSL3-5	100	1492-PSL3-5	100	1492-PSL3-5	100	1492-PSL3-5	100	1492-PSL3-5	100
Reducing Sleeves #18 AWG (0.75...1.0 mm ²) Dark Grey	1492-PSL3-10	100	1492-PSL3-10	100	1492-PSL3-10	100	1492-PSL3-10	100	1492-PSL3-10	100	1492-PSL3-10	100
Test Plug	1492-TP23	20	1492-TP23	20	1492-TP23	20	1492-TP23	20	1492-TP23	20	1492-TP23	20
Test Plug (Stackable)	1492-TPL5	25	1492-TPL5	25	1492-TPL5	25	1492-TPL5	25	1492-TPL5	25	1492-TPL5	25
Electrical Warning Plate	1492-EWPL5	20	1492-EWPL5	20	1492-EWPL5	20	1492-EWPL5	20	1492-EWPL5	20	1492-EWPL5	20
Group Marking Carrier	1492-GM35	25	1492-GM35	25	1492-GM35	25	1492-GM35	25	1492-GM35	25	1492-GM35	25
Marking Systems												
Snap-In Marker Cards	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5
Snap-In Marker Cards	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5
Hinged Marker Cards	1492-MH5X10 (96/card)	5	1492-MH5X10 (96/card)	5	1492-MH5X10 (96/card)	5	1492-MH5X10 (96/card)	5	1492-MH5X10 (96/card)	5	1492-MH5X10 (96/card)	5