



Spring-Clamp Connection Terminal Blocks

Plug-in Connection Blocks

1492-LC3

1492-LDC3

Dimensions are not intended to be used for manufacturing purposes.
Note: Height dimension is measured from top of rail to top of terminal block.

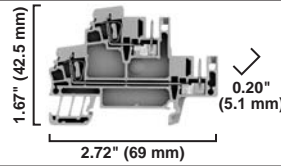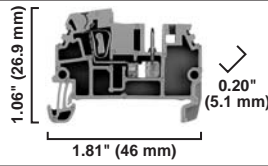

Specifications	1492-LC3			1492-LDC3		
Feed-through terminal block with plug in comb connection on one side.				Two Circuit terminal block with plug in comb connection on one side of each circuit		
Certifications		CSA	IEC		CSA	IEC
Voltage Rating	300V AC/DC			300V AC/DC		
Maximum Current	10 A			10 A		
Wire Range (Rated Cross Section)	#26...12 AWG			#26...14 AWG		
Wire Strip Length	0.39 in. (10 mm)			0.39 in. (10 mm)		
Density	59 pcs/ft (196 pcs/m)			59 pcs/ft (196 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)			-58...+248 °F (-50...+120 °C)		
Terminal Blocks	Cat. No.	Pkg Qty.		Cat. No.	Pkg Qty.	
Color Gray	1492-LC3	50		1492-LDC3	50	
Plug Connection Strips	Cat. No.	Pkg Qty.		Cat. No.	Pkg Qty.	
Color/Quantity Black/2-Pole	1492-QP5-2	100		1492-QP5-2	100	
Black/3-Pole	1492-QP5-3	100		1492-QP5-3	100	
Black/4-Pole	1492-QP5-4	100		1492-QP5-4	100	
Black/5-Pole	1492-QP5-5	50		1492-QP5-5	50	
Black/6-Pole	1492-QP5-6	50		1492-QP5-6	50	
Black/7-Pole	1492-QP5-7	50		1492-QP5-7	50	
Black/8-Pole	1492-QP5-8	50		1492-QP5-8	50	
Black/9-Pole	1492-QP5-9	50		1492-QP5-9	50	
Black/10-Pole	1492-QP5-10	50		1492-QP5-10	50	
Black/11-Pole	1492-QP5-11	50		1492-QP5-11	50	
Black/12-Pole	1492-QP5-12	50		1492-QP5-12	50	
Accessories	Cat. No.	Pkg Qty.		Cat. No.	Pkg Qty.	
Mounting Rails						
1 m Symmetrical DIN (Steel)	199-DR1	10		199-DR1	10	
1 m Symmetrical DIN (Aluminum)	1492-DR5	10		1492-DR5	10	
1 m Hi-Rise Sym. DIN (Aluminum)	1492-DR6	2		1492-DR6	2	
1 m Angled Hi-Rise Sym. DIN (Steel)	1492-DR7	2		1492-DR7	2	
End Barriers Grey	1492-EBLC3	20		1492-EBLDC3	20	
End Anchors and Retainers:						
Screwless End Retainer	1492-ERL35	20		1492-ERL35	20	
DIN Rail — Normal Duty	1492-EAJ35	100		1492-EAJ35	100	
DIN Rail — Heavy Duty	1492-EAHJ35	50		1492-EAHJ35	50	
Jumpers						
Plug-in Center Jumper — 50-Pole	1492-CJLJ5-50	10		1492-CJLJ5-50	10	
Plug-in Center Jumper — 10-Pole	1492-CJLJ5-10	20		1492-CJLJ5-10	20	
Plug-in Center Jumper — 9-Pole	1492-CJLJ5-9	20		1492-CJLJ5-9	20	
Plug-in Center Jumper — 8-Pole	1492-CJLJ5-8	20		1492-CJLJ5-8	20	
Plug-in Center Jumper — 7-Pole	1492-CJLJ5-7	20		1492-CJLJ5-7	20	
Plug-in Center Jumper — 6-Pole	1492-CJLJ5-6	20		1492-CJLJ5-6	20	
Plug-in Center Jumper — 5-Pole	1492-CJLJ5-5	20		1492-CJLJ5-5	20	
Plug-in Center Jumper — 4-Pole	1492-CJLJ5-4	60		1492-CJLJ5-4	60	
Plug-in Center Jumper — 3-Pole	1492-CJLJ5-3	60		1492-CJLJ5-3	60	
Plug-in Center Jumper — 2-Pole	1492-CJLJ5-2	60		1492-CJLJ5-2	60	
Other Accessories						
Group Marking Carrier	1492-GM35	25		1492-GM35	25	
Marking Systems						
Snap-In Marker Cards	1492-M5X10 (144/card)	5		1492-M5X10 (144/card)	5	
Snap-In Marker Cards	1492-M5X5 (200/card)	5		1492-M5X5 (200/card)	5	
Hinged Marker Card	1492-MH5X10 (96/card)	5		—	—	