



Spring-Clamp Connection Terminal Blocks

Multi-Circuit Feed-Through Blocks

1492-LD4

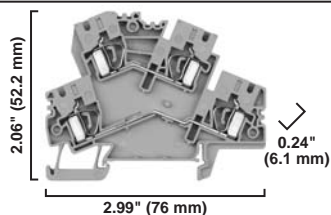

1492-LTF3

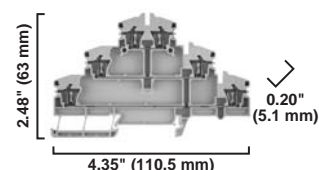

Dimensions are not intended to be used for manufacturing purposes.

Note: Height dimension is measured from top of rail to top of terminal block.

Specifications

Certifications	Two-circuit feed-through terminal block			Three-circuit feed-through terminal block with multiple cross connection points		
		CSA	IEC		CSA	IEC
Voltage Rating	600V AC/DC		800V AC/DC	300V AC/DC		500V AC/DC
Maximum Current	25 A	30 A	32 A	15 A	20 A	
Wire Range (Rated Cross Section)	#26...10 AWG		4 mm ²	#26...12 AWG		2.5 mm ²
Wire Strip Length	0.39 in. (10 mm)			0.39 in. (10 mm)		
Density	49 pcs/ft (163 pcs/m)			59 pcs/ft (196 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)			-58...+248 °F (-50...+120 °C)		

Terminal Blocks

		Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Color	Grey	1492-LD4	20	1492-LTF3	25
	Red	1492-LD4-RE	20	—	—
	Blue	1492-LD4-B	20	—	—
	Black	1492-LD4-BL	20	—	—
	Green	1492-LD4-G	20	—	—
	Yellow	1492-LD4-Y	20	—	—
	Orange	1492-LD4-OR	20	—	—
	Brown	1492-LD4-BR	20	—	—
	White	1492-LD4-W	20	—	—

Accessories

		Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Mounting Rails	1 m Symmetrical DIN (Steel)	199-DR1	10	199-DR1	10
	1 m Symmetrical DIN (Aluminum)	1492-DR5	10	1492-DR5	10
	1 m Hi-Rise Sym. DIN (Aluminum)	1492-DR6	2	1492-DR6	2
	1 m Angled Hi-Rise Sym. DIN (Steel)	1492-DR7	2	1492-DR7	2
End Barriers	Grey	1492-EBLD4	20	1492-EBLTF3	20
	Blue	1492-EBLD4-B	20	—	—
	Yellow	1492-EBLD4-Y	20	—	—
End Anchors and Retainers	Screwless End Retainer	1492-ERL35	20	1492-ERL35	20
	DIN Rail — Normal Duty	1492-EAJ35	100	1492-EAJ35	100
	DIN Rail — Heavy Duty	1492-EAHJ35	50	1492-EAHJ35	50
Jumpers	Plug-in Center Jumper — 50-Pole	—	—	1492-CJK5-50	10
	Plug-in Center Jumper — 10-Pole	1492-CJK6-10	20	1492-CJK5-10	20
	Plug-in Center Jumper — 9-Pole	1492-CJK6-9	20	1492-CJK5-9	20
	Plug-in Center Jumper — 8-Pole	1492-CJK6-8	20	1492-CJK5-8	20
	Plug-in Center Jumper — 7-Pole	1492-CJK6-7	20	1492-CJK5-7	20
	Plug-in Center Jumper — 6-Pole	1492-CJK6-6	20	1492-CJK5-6	20
	Plug-in Center Jumper — 5-Pole	1492-CJK6-5	20	1492-CJK5-5	20
	Plug-in Center Jumper — 4-Pole	1492-CJK6-4	60	1492-CJK5-4	60
	Plug-in Center Jumper — 3-Pole	1492-CJK6-3	60	1492-CJK5-3	60
	Plug-in Center Jumper — 2-Pole	1492-CJK6-2	60	1492-CJK5-2	60
	Vertical Cross Connector*	—	—	1492-CJL5D	20
Other Accessories	Reducing Sleeves 26...24 AWG (0.13...0.2 mm ²)	—	—	1492-PSLTF3-2	100
	Reducing Sleeves 22...20 AWG (0.25...0.5 mm ²)	—	—	1492-PSLTF3-5	100
	Test Plug	1492-TP23	20	—	—
	Electrical Warning Plate	1492-EWPL6	20	—	—
Marking Systems	Snap-In Marker Cards	1492-M6X10 (120/card)	5	1492-SM5X10 (144/card)	5
	Snap-In Marker Cards	1492-M6X5 (200/card)	5	1492-M5X5 (200/card)	5

* Used to electrically connect 2 levels of 1492-LTF3