
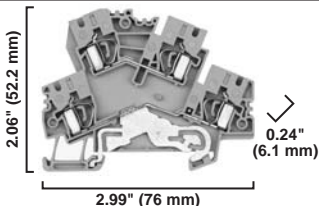


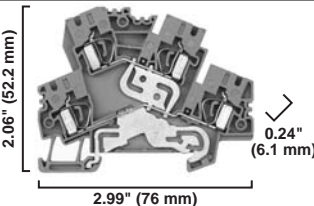

## Spring-Clamp Connection Terminal Blocks

Grounding Blocks, Continued

	1492-LDG4			1492-LDG4C		
Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block.						
	<i>Two-Circuit Block with 1 Feed-Through and 1 Ground Circuit</i>			<i>Single-Circuit, Two-level Ground Block with 2 Connection Points on Each Side</i>		
<b>Specifications</b>						
Certifications		CSA	IEC		CSA	IEC
Voltage Rating	600V AC/DC			800V AC/DC		
Maximum Current	25 A	30 A	32 A	Grounding		
Wire Range (Rated Cross Section)	#26...10 AWG		4 mm <sup>2</sup>	#26...10 AWG		4 mm <sup>2</sup>
Wire Strip Length	0.39 in. (10 mm)			0.39 in. (10 mm)		
Density	49 pcs/ft (163 pcs/m)			49 pcs/ft (163 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)			-58...+248 °F (-50...+120 °C)		
<b>Terminal Blocks</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>
Color:	Green/Yellow	—	—	<b>1492-LDG4C</b>	—	20
	Grey	1492-LDG4	20	—	—	—
<b>Accessories</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>	<b>Cat. No.</b>	<b>Pkg Qty.</b>
Mounting Rails:						
1 m Symmetrical DIN (Steel)	<b>199-DR1</b>	10	<b>199-DR1</b>	10		
1 m Symmetrical DIN (Aluminum)	<b>1492-DR5</b>	10	<b>1492-DR5</b>	10		
1 m Hi-Rise Symmetrical DIN (Aluminum)	<b>1492-DR6</b>	2	<b>1492-DR6</b>	2		
1 m Angled Hi-Rise Sym. DIN (Steel)	<b>1492-DR7</b>	2	<b>1492-DR7</b>	2		
End Barrier	Yellow	—	<b>1492-EBLD4-Y</b>	20		
	Grey	<b>1492-EBLD4</b>	20	—		
End Anchors and Retainers						
Screwless End Retainer	<b>1492-ERL35</b>	20	<b>1492-ERL35</b>	20		
DIN Rail — Normal Duty	<b>1492-EAJ35</b>	100	<b>1492-EAJ35</b>	100		
DIN Rail — Heavy Duty	<b>1492-EAHJ35</b>	50	<b>1492-EAHJ35</b>	50		
Other Accessories:						
Test Plug	<b>1492-TP23</b>	20	—	—		
Electrical Warning Plate	<b>1492-EWPL6</b>	20	—	—		
Group Marking Carrier	<b>1492-GM35</b>	25	<b>1492-GM35</b>	25		
Marking Systems:						
Snap-In Marker Cards	<b>1492-M6X10</b> (120/card)	5	<b>1492-M6X10</b> (120/card)	5		
Snap-In Marker Cards	<b>1492-M6X5</b> (200/card)	5	<b>1492-M6X5</b> (200/card)	5		