



Spring-Clamp Connection Terminal Blocks

Mini-Blocks with Center Jumper Option

1492-LMJ3

1492-LMJG3

Dimensions are not intended to be used for manufacturing purposes.
Note: Height dimension is measured from top of rail to top of terminal block.

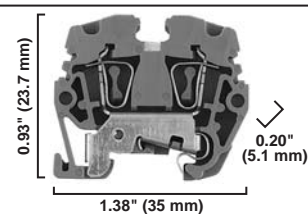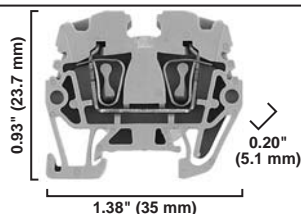

Specifications	Mini rail-mount, Feed-through Terminal Block with jumper capability				Mini rail-mount grounding Terminal Block		
Certifications		CSA	IEC	ATEX		CSA	IEC
Voltage Rating	600V AC/DC			500V AC/DC	275V AC/DC	—	—
Maximum Current	20 A			24 A	20 A	Grounding	
Wire Range (Rated Cross Section)	#26...12 AWG			2.5 mm ²	#20...12 AWG	2.5 mm ²	
Wire Strip Length	0.39 in. (10 mm)				0.39 in. (10 mm)		
Density	59 pcs/ft (196 pcs/m)				59 pcs/ft (196 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)		
Terminal Blocks		Cat. No.	Pkg Qty.		Cat. No.	Pkg Qty.	
Color	Grey	1492-LMJ3	100		—	—	
	Blue	1492-LMJ3-B	100		—	—	
	Green/Yellow	—	—		1492-LMJG3	100	
Accessories		Cat. No.	Pkg Qty.		Cat. No.	Pkg Qty.	
Mounting Rails		1492-DR3	5		1492-DR3	5	
1 m Symmetrical DIN (Steel)							
Screwless End Retainer	Grey	1492-ERL15	20		1492-ERL15	20	
End Anchor	Grey	1492-EAJ15	50		1492-EAJ15	50	
Jumpers							
Plug-in Center Jumper — 50-Pole		1492-CJLJ5-50	10		—	—	
Plug-in Center Jumper — 10-Pole		1492-CJLJ5-10	20		—	—	
Plug-in Center Jumper — 9-Pole		1492-CJLJ5-9	20		—	—	
Plug-in Center Jumper — 8-Pole		1492-CJLJ5-8	20		—	—	
Plug-in Center Jumper — 7-Pole		1492-CJLJ5-7	20		—	—	
Plug-in Center Jumper — 6-Pole		1492-CJLJ5-6	20		—	—	
Plug-in Center Jumper — 5-Pole		1492-CJLJ5-5	20		—	—	
Plug-in Center Jumper — 4-Pole		1492-CJLJ5-4	60		—	—	
Plug-in Center Jumper — 3-Pole		1492-CJLJ5-3	60		—	—	
Plug-in Center Jumper — 2-Pole		1492-CJLJ5-2	60		—	—	
Side Jumper — 2-Pole		1492-SJLM5-2	50		—	—	
Side Jumper Installation Tool		1492-TAL5-2	1		—	—	
End Barriers							
	Grey	1492-EBLMJ3	50		1492-EBLMJ3	50	
	Blue	1492-EBLMJ3-B	50		1492-EBLMJ3-B	50	
	Yellow	1492-EBLMJ3-Y	50		1492-EBLMJ3-Y	50	
Marking Systems							
Snap-in Marker Cards		1492-SM5X10 (144/card)	5		1492-SM5X10 (144/card)	5	
Snap-In Marker Cards*		1492-M5X5 (200/card)	5		1492-M5X5 (200/card)	5	
Hinged marker cards*		1492-MH5X10 (96/card)	5		1492-MH5X10 (96/card)	5	

* Markers can be installed over center jumper channel, with or without center jumper installed.