


1756-OF8I (Voltage) with 1492-AIFM6S-3 or 1492-RAIFM6S-3

1756-OF6VI (VOLTAGE) TO 1756-OF8I (VOLTAGE)

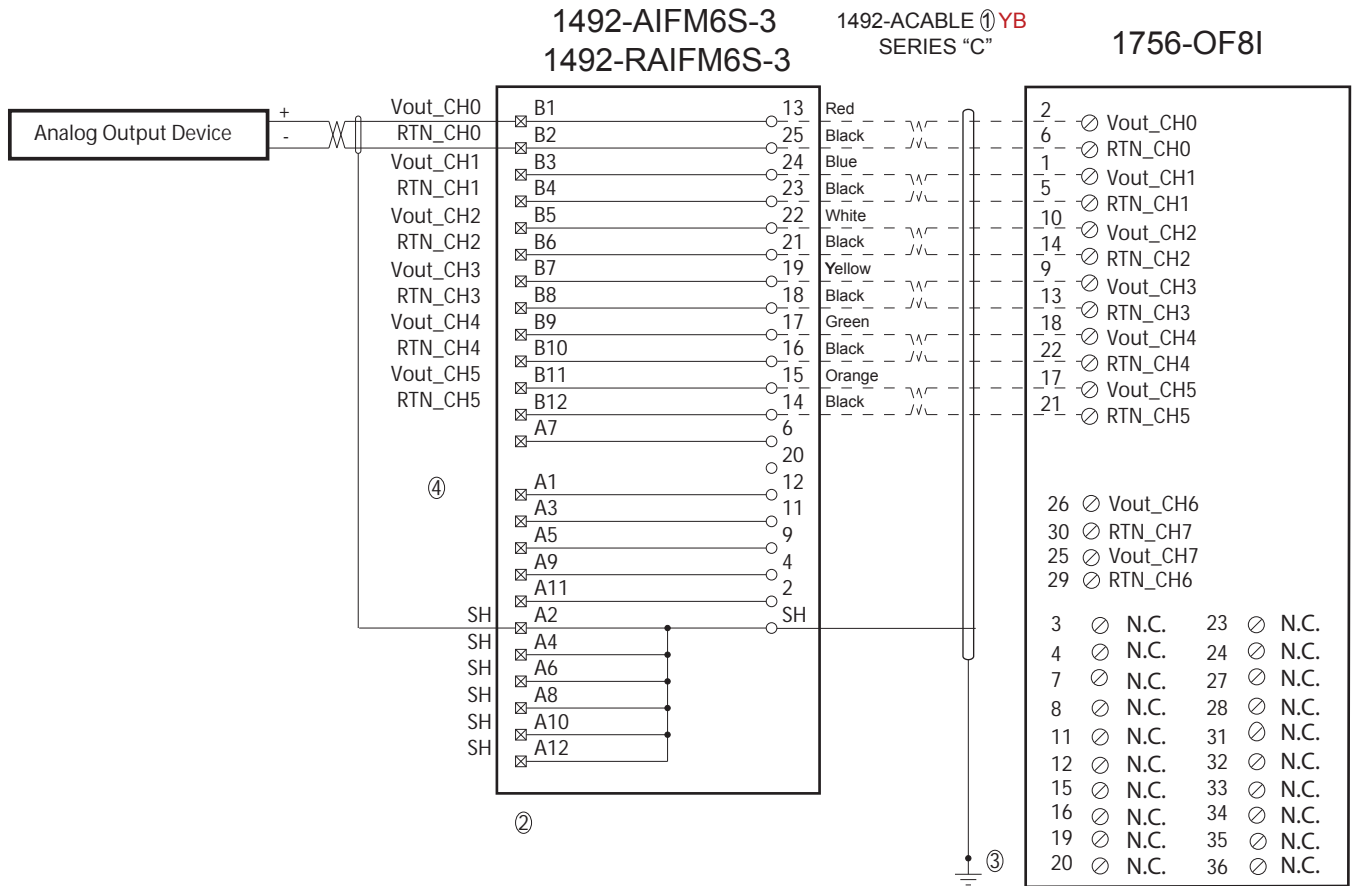

- ① Cables are available in 0.5m, 1.0m, 2.5m, and 5.0m standard lengths (005=0.5m, 010=1.0m, 025=2.5m, 050=5.0m). Custom length cables are also available.
- ② Terminals starting with A are the lower row of terminals, B terminals are the upper row.
- ③ Follow your PLC Analog User Manual for proper shield grounding instructions.
- ④ Do NOT make connections on terminal A7 as it may affect proper operation.

