


	1	2	3	4	5	6	7	8
A	Rockwell Part Number	43GR-TMC25SL						
	Drawing	75007-032-01						
	Fiber Amplifier Diameter	4.6 mm						
	Core Diameter	3.2 mm (Randomized)						
	Flex Relief	No						
	Fiber Optic Material	Glass						
	Fiber Optic Type	Diffuse (Bifurcated)						
B	Sensing End Material	Brass and Stainless Steel						
	Fiber Tip Size	5/16 x 24 UNF						
	Minimum Bend Radius	19 mm						
	Jacket Material	Stainless Steel						
	Temperature	- 55 °C to +260 °C						
	Fiber Optic Length	0.91 m (36 in.)						

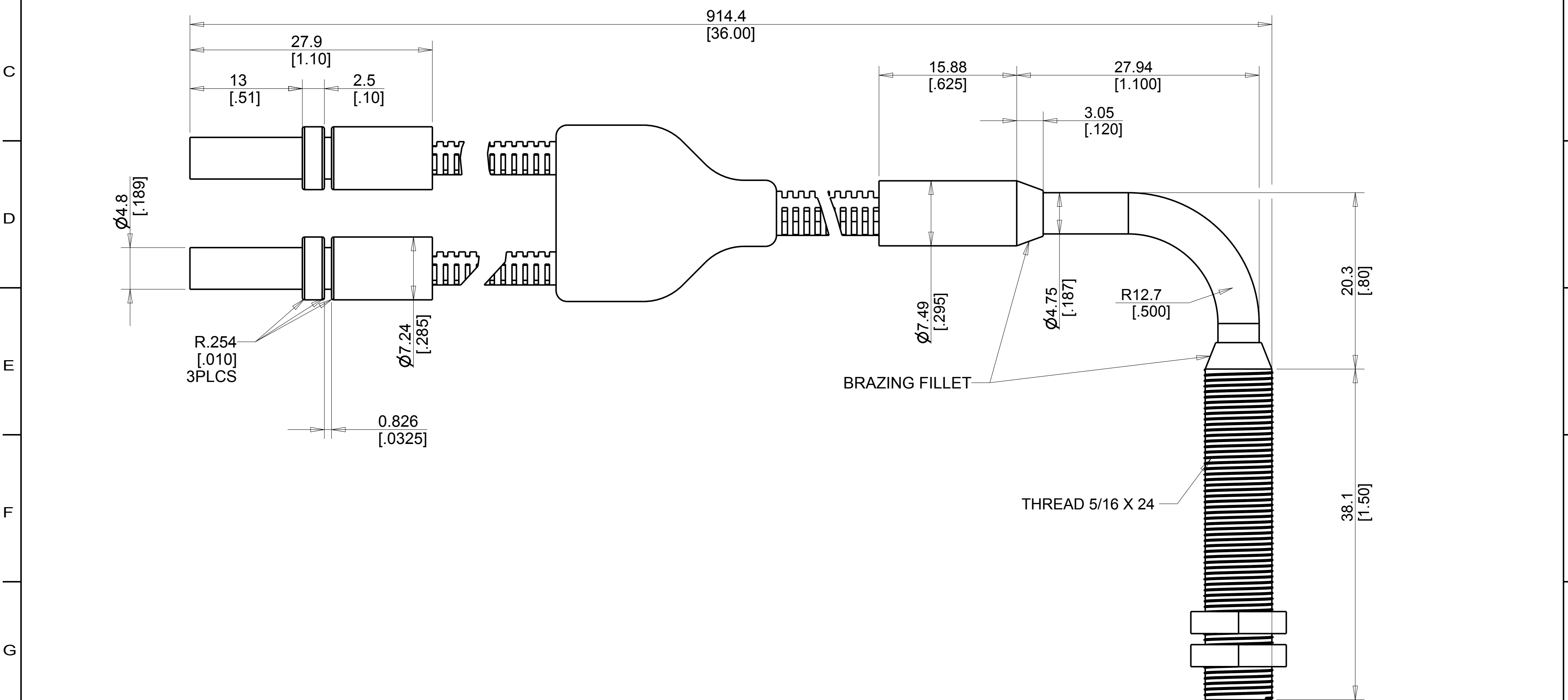

ALL DIMENSIONS ARE MM [INCHES]

NOTES:
 1. Standard Length of 36" in shown.
 2. Longer fiber optic cable lengths are available in increments of 36 inches (0.9 m) up to 50 Ft.(15.2 m). Please contact your local Rockwell Automation Distributor for More Information.

SCALE 3:1

Rockwell Automation		CONFIDENTIAL AND PROPRIETARY INFORMATION. THIS DOCUMENT CONTAINS CONFIDENTIAL AND PROPRIETARY INFORMATION OF ROCKWELL AUTOMATION, INC. AND MAY NOT BE USED, COPIED OR DISCLOSED TO OTHERS, EXCEPT WITH THE AUTHORIZED WRITTEN PERMISSION OF ROCKWELL AUTOMATION, INC.	
43gr-tmc25sl.drw		Sheet 1 Of 1	
Drawn by:LTTS	Date: 08/31/18	Size C	Ver