


Definite-Purpose Style Enclosures


Approximate Dimensions

Dimensions are shown in millimeters (inches). Dimensions are not intended to be used for manufacturing purposes.

General Purpose Enclosures

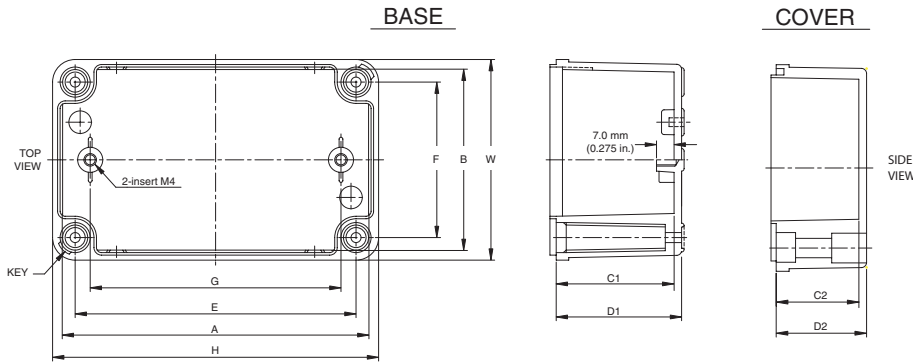

Cat. No.	Overall Dimension				Inside Dimension				Enclosure Mounting Dimension		Mounting Plate Mounting Dim.
	H	W	D1	D2	A	B	C1	C2	E	F	
598-BS533	130 (5.12)	80 (3.15)	50 (1.97)	35 (1.38)	120 (4.72)	70 (2.76)	46.5 (1.83)	31.5 (1.24)	112 (4.41)	62 (2.44)	100 (3.94)
598-BS733	180 (7.09)	80 (3.15)	50 (1.97)	35 (1.38)	170 (6.69)	70 (2.76)	46.5 (1.83)	31.5 (1.24)	162 (6.38)	62 (2.44)	150 (5.91)
598-BS933	250 (9.84)	80 (3.15)	50 (1.97)	35 (1.38)	240 (9.45)	70 (2.76)	46.5 (1.83)	31.5 (1.24)	232 (9.13)	62 (2.44)	220 (8.66)

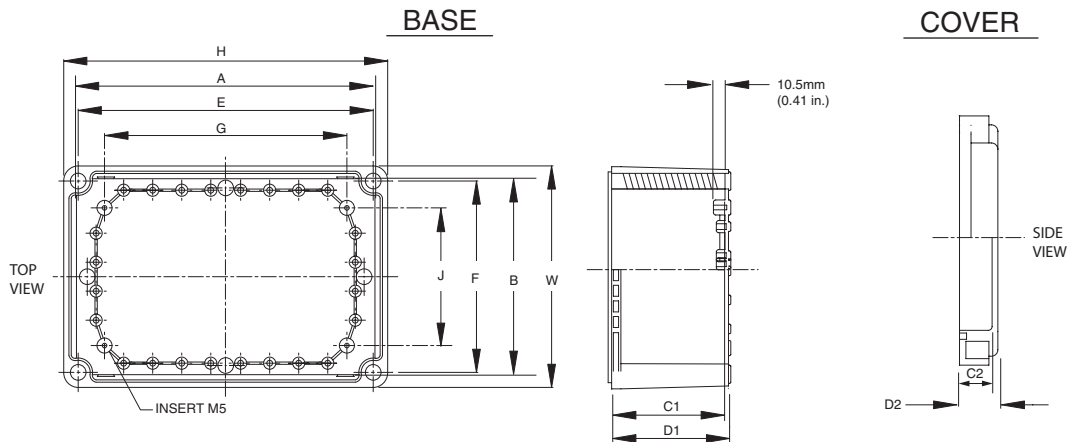

Cat. No.	Overall Dimension				Inside Dimension				Enclosure Mounting Dimension		Mounting Plate Mounting Dim.	
	H	W	D1	D2	A	B	C1	C2	E	F	G	J
598-BS885	190 (7.48)	190 (7.48)	98 (3.86)	30 (1.18)	174 (6.85)	174 (6.85)	94 (3.70)	26 (1.02)	165 (6.50)	165 (6.50)	120 (4.72)	120 (4.72)
598-DS885												
598-BS1187	280 (11.02)	190 (7.48)	98 (3.86)	80 (3.15)	266 (10.47)	170 (6.69)	94 (3.70)	76 (2.99)	255 (10.04)	165 (6.50)	210 (8.27)	120 (4.72)
598-DS1187												
598-BS1587	382 (15.04)	192 (7.56)	98 (3.86)	80 (3.15)	366 (14.41)	172 (6.77)	94 (3.70)	76 (2.99)	355 (13.98)	165 (6.50)	310 (12.20)	120 (4.72)
598-DS1587												
598-BS11115	280 (11.02)	280 (11.02)	98 (3.86)	30 (1.18)	260 (10.24)	260 (10.24)	94 (3.70)	26 (1.02)	255 (10.04)	255 (10.04)	210 (8.27)	210 (8.27)
598-DS11115												
598-BS13115	341 (13.43)	280 (11.02)	100 (3.94)	30 (1.18)	320 (12.60)	260 (10.24)	96 (3.78)	26 (1.02)	316 (12.44)	256 (10.08)	270 (10.63)	210 (8.27)
598-DS13115												
598-BS15117	380 (14.96)	280 (11.02)	98 (3.86)	80 (3.15)	359 (14.13)	259 (10.20)	94 (3.70)	76 (2.99)	355 (13.98)	255 (10.04)	310 (12.20)	210 (8.27)
598-DS15117												
598-BS22115	560 (22.05)	280 (11.02)	98 (3.86)	30 (1.18)	540 (21.26)	260 (10.24)	94 (3.70)	26 (1.02)	535 (21.06)	255 (10.04)	490 (19.29)	220 (8.66)
598-DS22115												
598-BS22157	560 (22.05)	380 (14.96)	148 (5.83)	30 (1.18)	540 (21.26)	360 (14.17)	144 (5.67)	26 (1.02)	535 (21.06)	355 (13.98)	490 (19.29)	311 (12.24)
598-DS22157												

Definite-Purpose Style Enclosures

Approximate Dimensions, Continued

Dimensions are shown in millimeters (inches). Dimensions are not intended to be used for manufacturing purposes.

General Purpose External Mounting Bracket for use with External Mounting Bracket

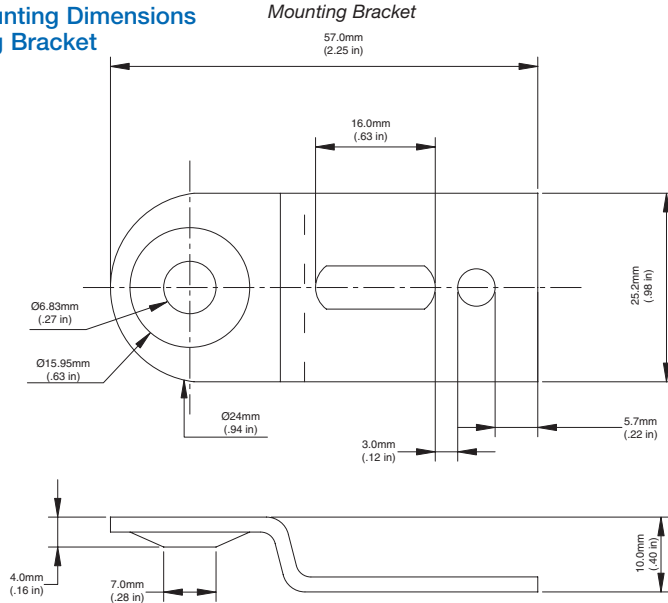


Fig. 1 – Base (Bottom View)

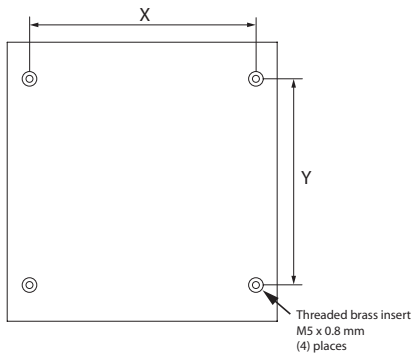


Fig. 2 – Base (Bottom View)

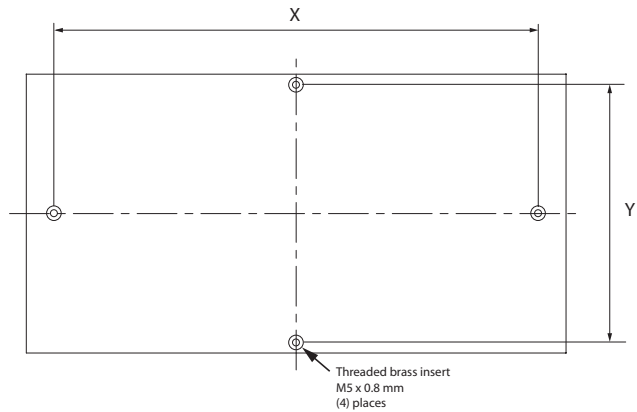


Fig. 3 – Base (Bottom View)


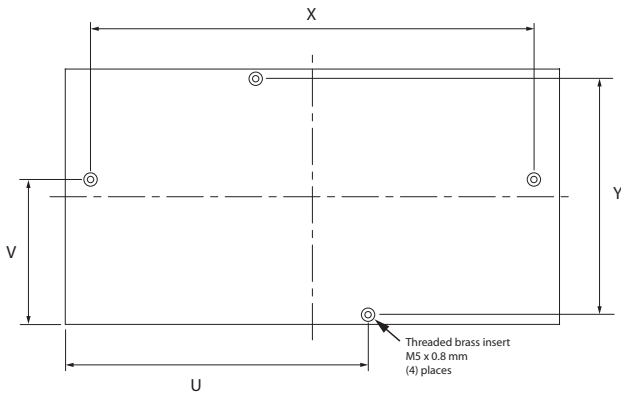


Fig. 4 – Base (Bottom View)

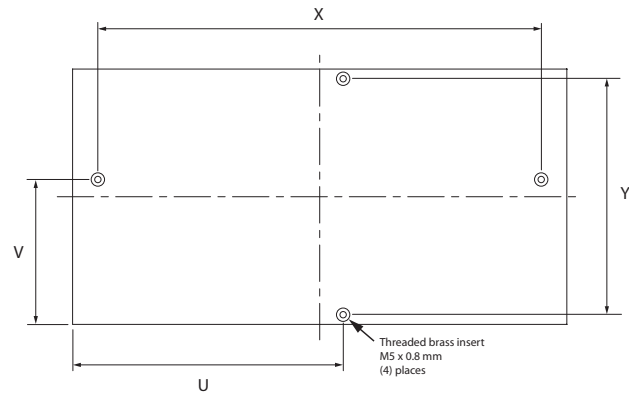

Cat. No.		Figure No.	U	V	X	Y
598-BS885__	598-DS885__	1	—	—	156 (6.13)	98 (3.88)
598-BS1187__	598-DS1187__	2	—	—	251 (9.88)	152 (6.00)
598-BS11115__	598-DS11115__		—	—	238 (9.38)	238 (9.38)
598-BS13115__	598-DS13115__		—	—	295 (11.63)	235 (9.25)
598-BS1587__	598-DS1587__		—	—	349 (13.78)	152 (6.00)
598-BS15117__	598-DS15117__		—	—	340 (13.38)	241 (9.50)
598-BS22115__	598-DS22115__	3	329 (12.94)	148 (5.81)	519 (20.44)	267 (10.50)
598-BS22157__	598-DS22157__	4	292 (11.50)	195 (7.69)	519 (20.44)	340 (13.38)