


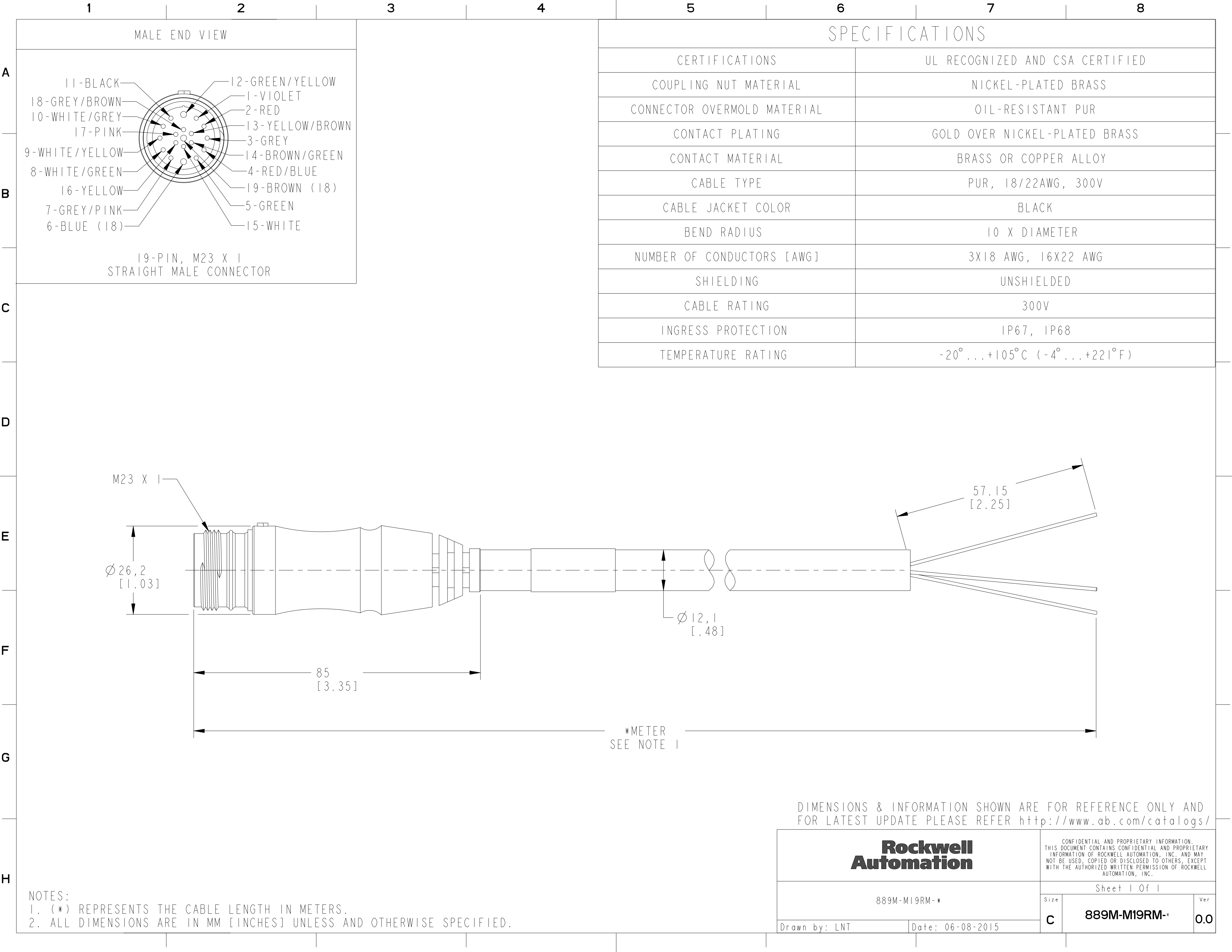


MALE END VIEW

- 11-BLACK
- 12-GREEN/YELLOW
- 18-GREY/BROWN
- 10-WHITE/GREY
- 17-PINK
- 9-WHITE/YELLOW
- 8-WHITE/GREEN
- 16-YELLOW
- 7-GREY/PINK
- 6-BLUE (18)
- 1-VIOLET
- 2-RED
- 13-YELLOW/BROWN
- 3-GREY
- 14-BROWN/GREEN
- 4-RED/BLUE
- 19-BROWN (18)
- 5-GREEN
- 15-WHITE

19-PIN, M23 X 1
STRAIGHT MALE CONNECTOR

SPECIFICATIONS

CERTIFICATIONS	UL RECOGNIZED AND CSA CERTIFIED
COUPLING NUT MATERIAL	NICKEL-PLATED BRASS
CONNECTOR OVERMOLD MATERIAL	OIL-RESISTANT PUR
CONTACT PLATING	GOLD OVER NICKEL-PLATED BRASS
CONTACT MATERIAL	BRASS OR COPPER ALLOY
CABLE TYPE	PUR, 18/22AWG, 300V
CABLE JACKET COLOR	BLACK
BEND RADIUS	10 X DIAMETER
NUMBER OF CONDUCTORS [AWG]	3X18 AWG, 16X22 AWG
SHIELDING	UNSHIELDED
CABLE RATING	300V
INGRESS PROTECTION	IP67, IP68
TEMPERATURE RATING	-20°...+105°C (-4°...+221°F)

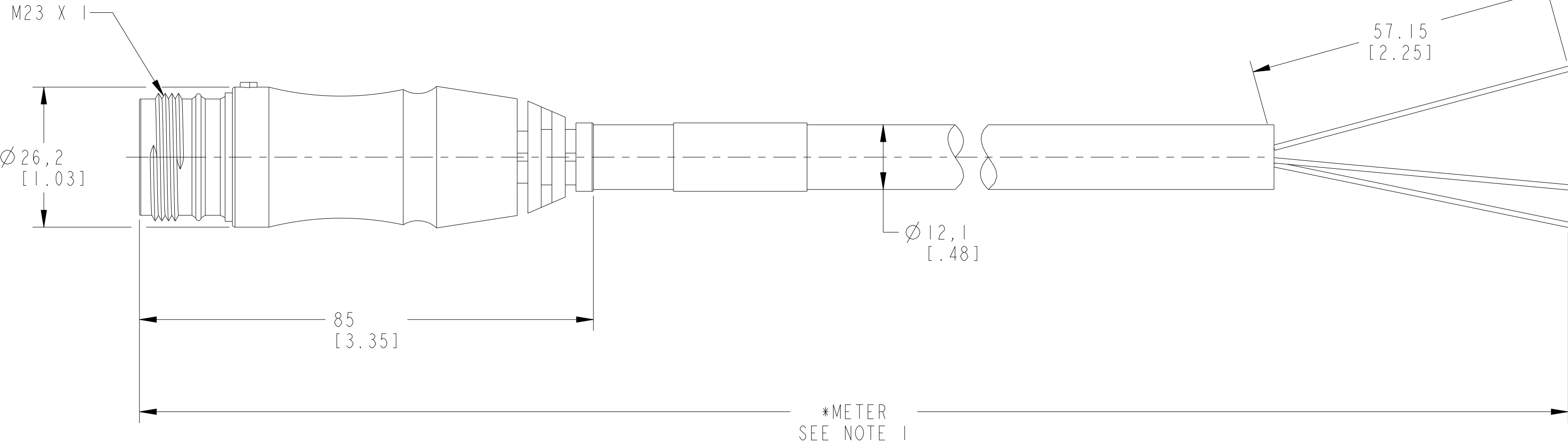

- NOTES:
- (*) REPRESENTS THE CABLE LENGTH IN METERS.
 - ALL DIMENSIONS ARE IN MM [INCHES] UNLESS AND OTHERWISE SPECIFIED.

DIMENSIONS & INFORMATION SHOWN ARE FOR REFERENCE ONLY AND
FOR LATEST UPDATE PLEASE REFER <http://www.ab.com/catalogs/>

Rockwell Automation		CONFIDENTIAL AND PROPRIETARY INFORMATION. THIS DOCUMENT CONTAINS CONFIDENTIAL AND PROPRIETARY INFORMATION OF ROCKWELL AUTOMATION, INC. AND MAY NOT BE USED, COPIED OR DISCLOSED TO OTHERS, EXCEPT WITH THE AUTHORIZED WRITTEN PERMISSION OF ROCKWELL AUTOMATION, INC.	
889M-M19RM-*		Sheet 1 Of 1	
Drawn by: LNT		Date: 06-08-2015	Ver
		C	889M-M19RM-* 0.0