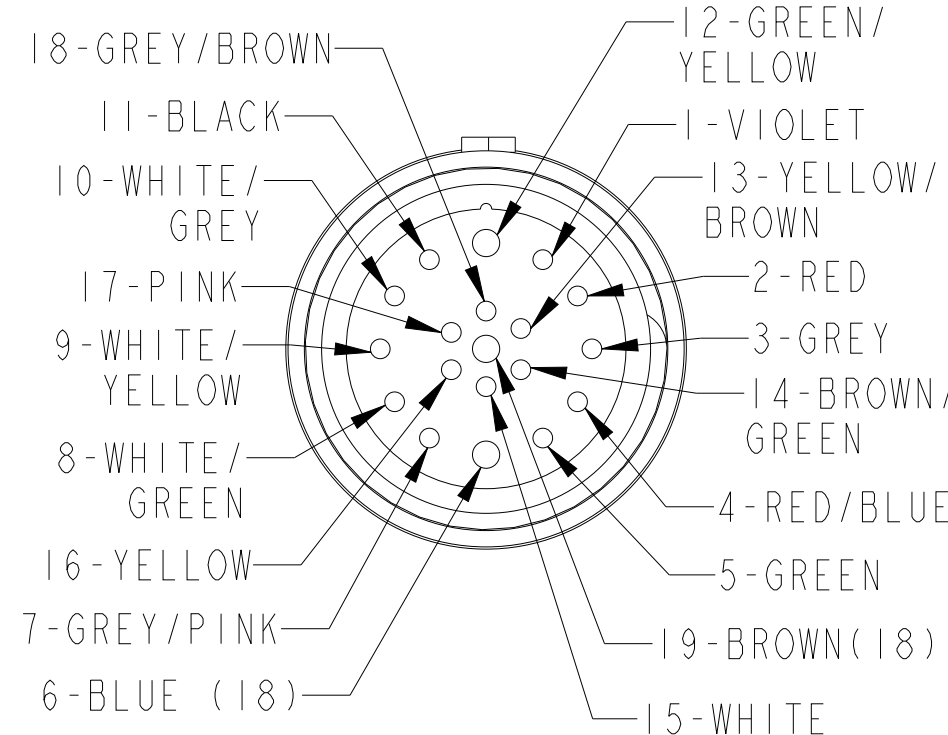
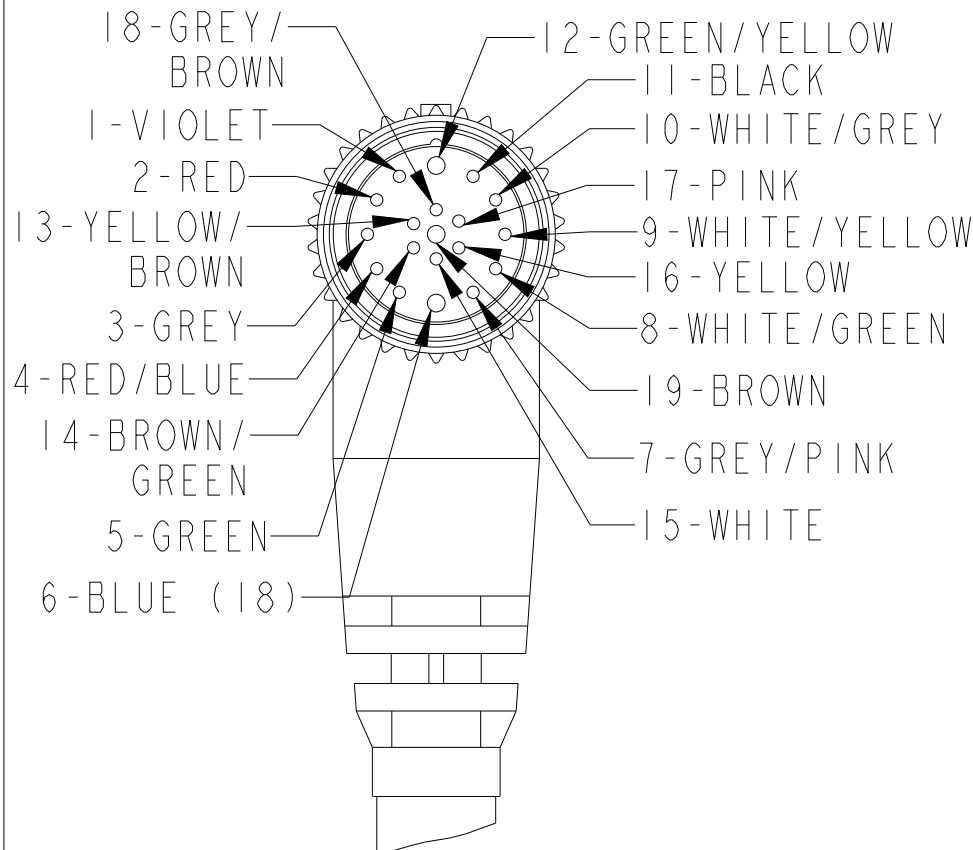
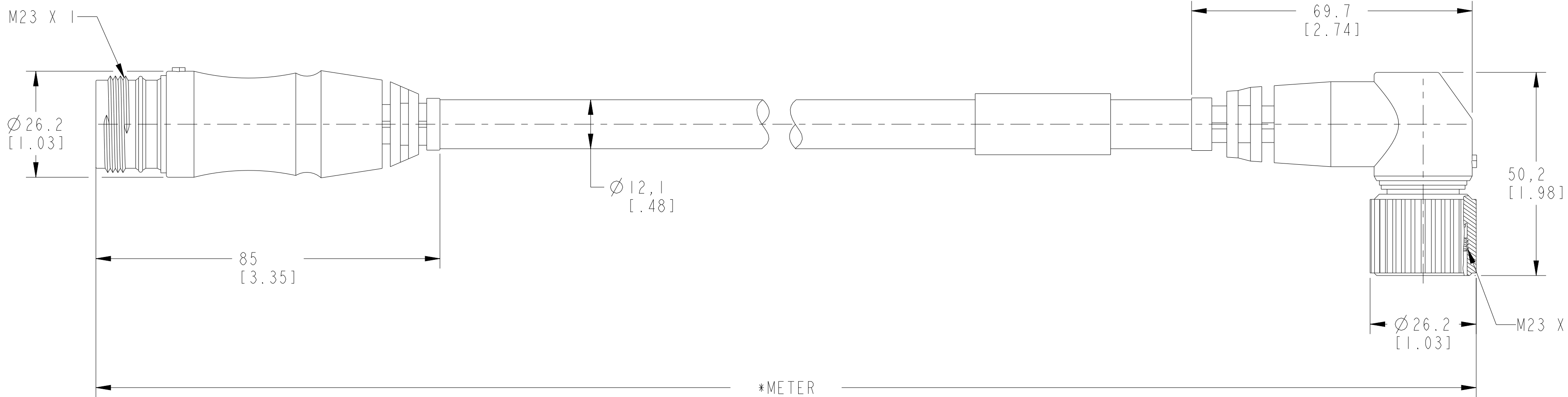


	1	2	3	4	5	6	7	8
	MALE END VIEW		RIGHT ANGLE FEMALE END VIEW		SPECIFICATIONS			
A					CERTIFICATIONS		UL RECOGNIZED AND CSA CERTIFIED	
					COUPLING NUT MATERIAL		NICKEL-PLATED BRASS	
CONNECTOR OVERMOLD MATERIAL					OIL-RESISTANT PUR			
CONTACT PLATING					GOLD OVER NICKEL-PLATED BRASS			
CONTACT MATERIAL					BRASS OR COPPER ALLOY			
B					CABLE TYPE		PUR, 18/22 AWG, 300V	
CABLE JACKET COLOR					BLACK			
BEND RADIUS					10 X DIAMETER			
NUMBER OF CONDUCTORS [AWG]					3X18/16X22 AWG (M23 MALE), 3X18/16X22 AWG (M23 FEMALE)			
C					SHIELDING		UNSHIELDED	
CABLE RATING					300V			
INGRESS PROTECTION					IP67, IP68			
TEMPERATURE RATING					-20°...+105°C (-4°...+221°F)			
D								
E								
F								
G								
H	<div>NOTES: 1. (*) REPRESENTS THE CABLE LENGTH IN METERS. 2. ALL DIMENSIONS ARE IN MM [INCHES] UNLESS AND OTHERWISE SPECIFIED.</div> <div><div><div>Rockwell Automation</div><div>889M-R19RMMM-*</div><div>Drawn by: LNT</div></div><div><div><div>DIMENSIONS & INFORMATION SHOWN ARE FOR REFERENCE ONLY AND FOR LATEST UPDATE PLEASE REFER http://www.ab.com/catalogs/</div><div><div>CONFIDENTIAL AND PROPRIETARY INFORMATION. THIS DOCUMENT CONTAINS CONFIDENTIAL AND PROPRIETARY INFORMATION OF ROCKWELL AUTOMATION, INC. AND MAY NOT BE USED, COPIED OR DISCLOSED TO OTHERS, EXCEPT WITH THE AUTHORIZED WRITTEN PERMISSION OF ROCKWELL AUTOMATION, INC.</div><div>Sheet 1 Of 1</div><div><div>Size</div><div>Ver</div></div></div><div><div>C</div><div>889M-R19RMMM-*</div><div>0.0</div></div><div><div>Date: 06-09-2015</div></div></div></div></div>							