
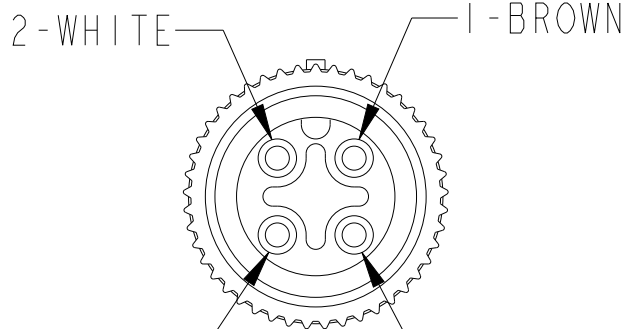
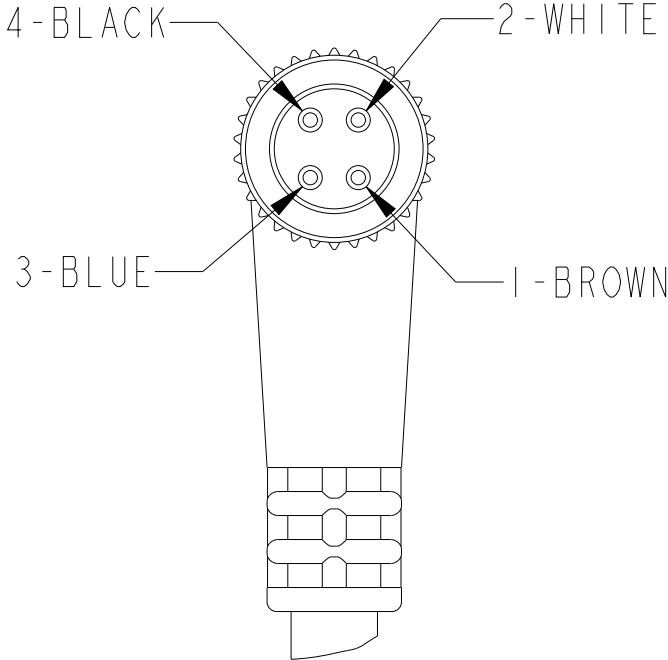



	1	2	3	4	5	6	7	8																										
	MALE END VIEW		RIGHT ANGLE FEMALE END VIEW		SPECIFICATIONS																													
A																																		
B	4-PIN M12 X 1 STRAIGHT MALE CONNECTOR		4-PIN, M8 X 1 RIGHT ANGLE FEMALE CONNECTOR																															
C					<table><tr><td>CERTIFICATIONS</td><td>UL RECOGNIZED AND CSA CERTIFIED</td></tr><tr><td>COUPLING NUT MATERIAL</td><td>NICKEL-PLATED BRASS</td></tr><tr><td>CONNECTOR OVERMOLD MATERIAL</td><td>OIL-RESISTANT PUR</td></tr><tr><td>CONTACT PLATING</td><td>GOLD OVER NICKEL-PLATED BRASS</td></tr><tr><td>CONTACT MATERIAL</td><td>BRASS OR COPPER ALLOY</td></tr><tr><td>CABLE TYPE</td><td>PVC, 24AWG, 300V</td></tr><tr><td>CABLE JACKET COLOR</td><td>YELLOW</td></tr><tr><td>BEND RADIUS</td><td>10 X DIAMETER</td></tr><tr><td>NUMBER OF CONDUCTORS [AWG]</td><td>4X24 AWG (MICRO MALE), 4X24 AWG (PICO FEMALE)</td></tr><tr><td>SHIELDING</td><td>UNSHIELDED</td></tr><tr><td>CABLE RATING</td><td>UL CM AWM STYLE 2661 VW-1 105C 300V, CSA AWM A/B 1/II 105C 300V FT1</td></tr><tr><td>INGRESS PROTECTION</td><td>IP67</td></tr><tr><td>TEMPERATURE RATING</td><td>-20° ... +105°C (-4° ... +221°F)</td></tr></table>				CERTIFICATIONS	UL RECOGNIZED AND CSA CERTIFIED	COUPLING NUT MATERIAL	NICKEL-PLATED BRASS	CONNECTOR OVERMOLD MATERIAL	OIL-RESISTANT PUR	CONTACT PLATING	GOLD OVER NICKEL-PLATED BRASS	CONTACT MATERIAL	BRASS OR COPPER ALLOY	CABLE TYPE	PVC, 24AWG, 300V	CABLE JACKET COLOR	YELLOW	BEND RADIUS	10 X DIAMETER	NUMBER OF CONDUCTORS [AWG]	4X24 AWG (MICRO MALE), 4X24 AWG (PICO FEMALE)	SHIELDING	UNSHIELDED	CABLE RATING	UL CM AWM STYLE 2661 VW-1 105C 300V, CSA AWM A/B 1/II 105C 300V FT1	INGRESS PROTECTION	IP67	TEMPERATURE RATING	-20° ... +105°C (-4° ... +221°F)
CERTIFICATIONS	UL RECOGNIZED AND CSA CERTIFIED																																	
COUPLING NUT MATERIAL	NICKEL-PLATED BRASS																																	
CONNECTOR OVERMOLD MATERIAL	OIL-RESISTANT PUR																																	
CONTACT PLATING	GOLD OVER NICKEL-PLATED BRASS																																	
CONTACT MATERIAL	BRASS OR COPPER ALLOY																																	
CABLE TYPE	PVC, 24AWG, 300V																																	
CABLE JACKET COLOR	YELLOW																																	
BEND RADIUS	10 X DIAMETER																																	
NUMBER OF CONDUCTORS [AWG]	4X24 AWG (MICRO MALE), 4X24 AWG (PICO FEMALE)																																	
SHIELDING	UNSHIELDED																																	
CABLE RATING	UL CM AWM STYLE 2661 VW-1 105C 300V, CSA AWM A/B 1/II 105C 300V FT1																																	
INGRESS PROTECTION	IP67																																	
TEMPERATURE RATING	-20° ... +105°C (-4° ... +221°F)																																	

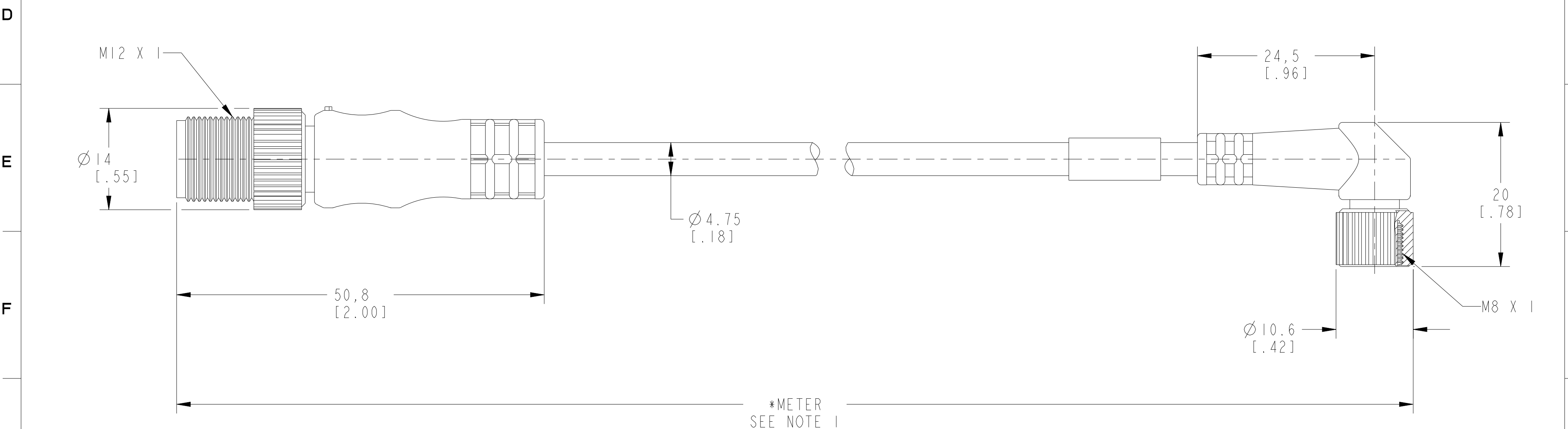

DIMENSIONS & INFORMATION SHOWN ARE FOR REFERENCE ONLY AND FOR LATEST UPDATE PLEASE REFER <http://www.ab.com/catalogs/>

		CONFIDENTIAL AND PROPRIETARY INFORMATION. THIS DOCUMENT CONTAINS CONFIDENTIAL AND PROPRIETARY INFORMATION OF ROCKWELL AUTOMATION, INC. AND MAY NOT BE USED, COPIED OR DISCLOSED TO OTHERS, EXCEPT WITH THE AUTHORIZED WRITTEN PERMISSION OF ROCKWELL AUTOMATION, INC.	
		Sheet   Of	
889P-R4ABDM-*		Size	Ver
Drawn by: LNT		C	889P-R4ABDM-* 0.0
Date: 03-12-2015			

NOTES:  
1. (\*) REPRESENTS THE CABLE LENGTH IN METERS.  
2. ALL DIMENSIONS ARE IN MM [INCHES] UNLESS AND OTHERWISE SPECIFIED.