



Bulletin 150
Smart Motor Controllers — SMC-3™
 Trip and Starts per Hour Curves

SMC-3 Overload Trip Curves


Trip Class 10

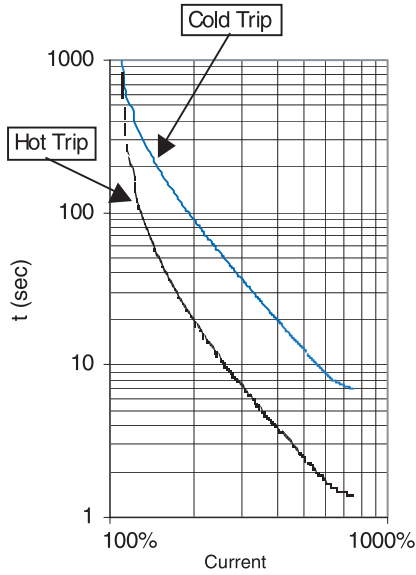

Trip Class 15

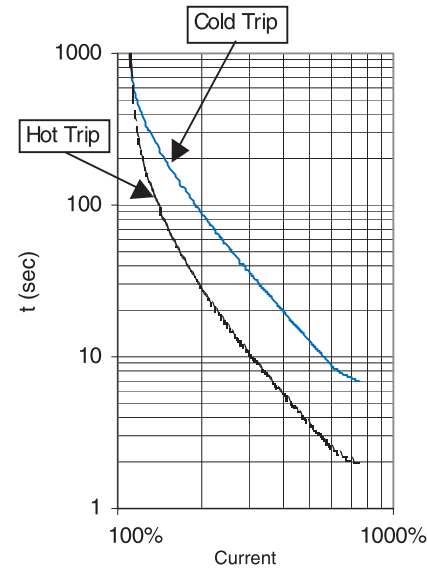


Trip Class 20

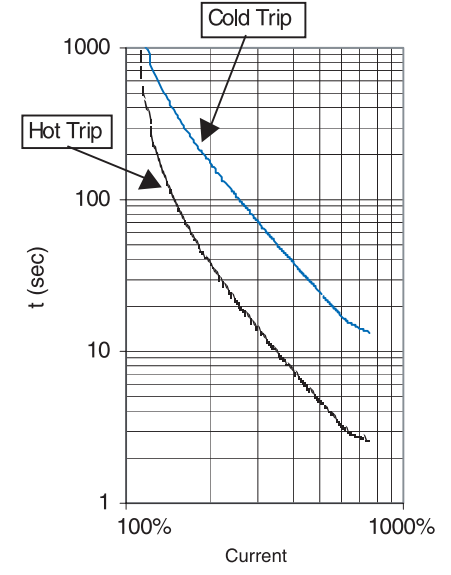


Starts per Hour Curves


SMC-3 Starts per hour
 40C, 100% duty cycle 10sec, 350%, No Fan

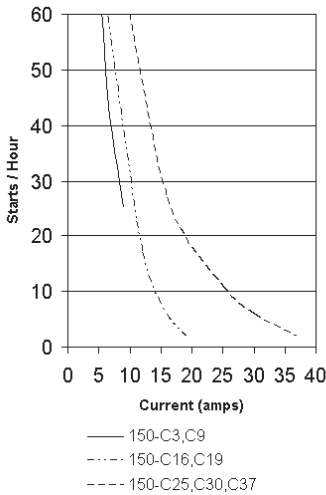


SMC-3 Starts per hour
 40C, 100% Duty Cycle, 10sec, 350% with Fan

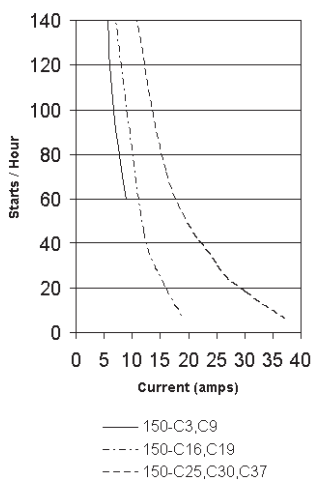

SMC-3 Starts per hour (14-85A)
 40C, 100% Duty Cycle, 20sec, 350% (with standard fan)

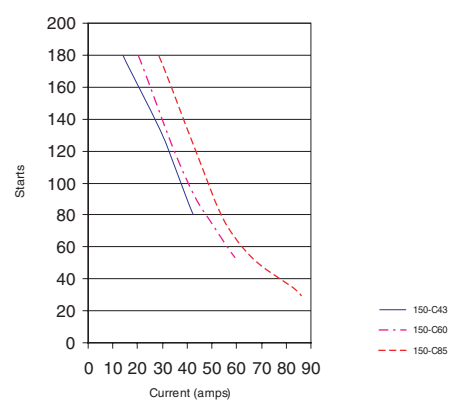

SMC-3 Starts per hour (108-135A)
 40C, 100% Duty Cycle, 20 sec, 350% (with standard fan)

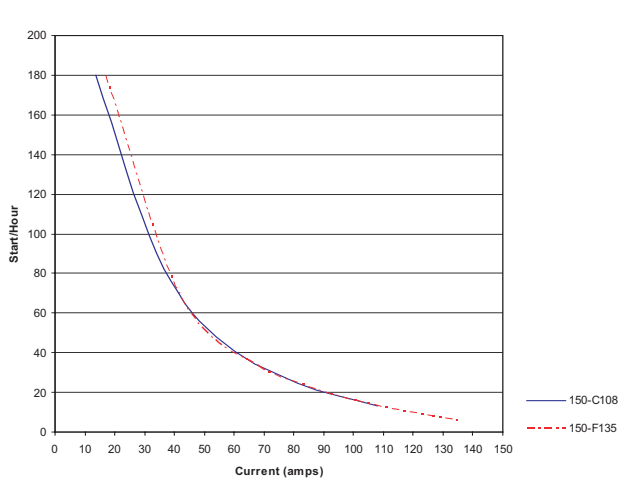

SMC-3 Starts per hour (201...480 A)
 40C, 100% Duty Cycle, 20 sec, 350% (with standard fan)

